





Product dimension (Unit: mm)

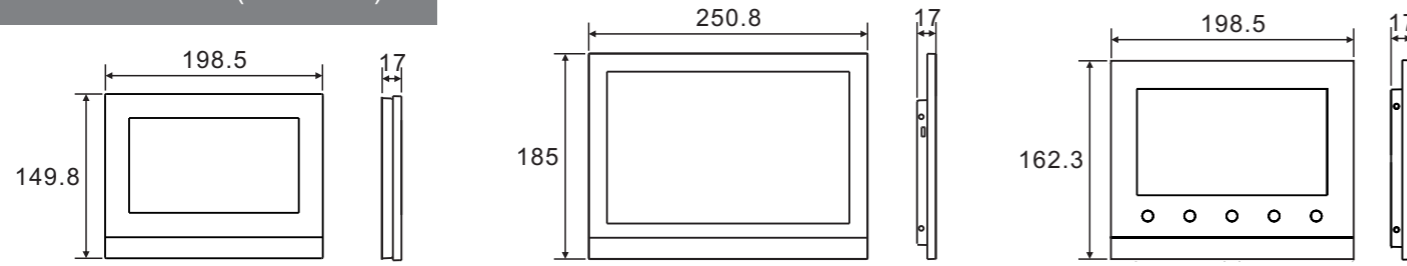

Installation height

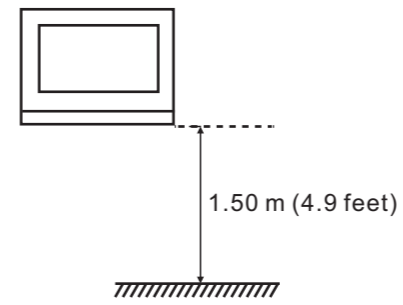

IPtouch 7

IPtouch 10

M2238.-.

Surface-mounted box (Unit: mm)

Global

VDE&BS&CN







NEMA

NEMA







NEMA&Italy

Swiss







IP touch 7

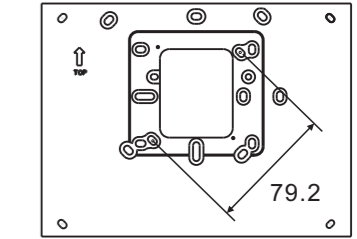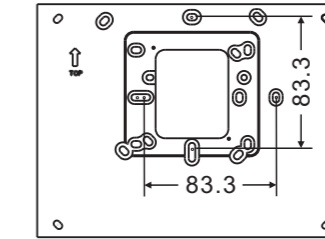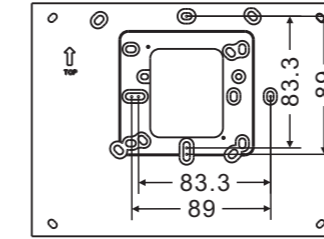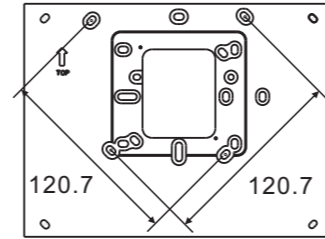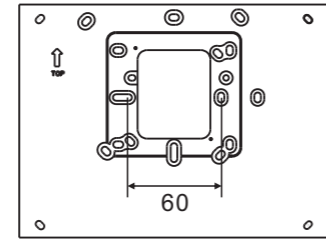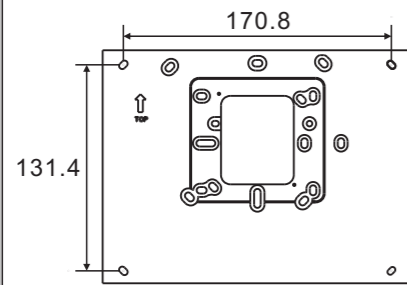

IP touch 10

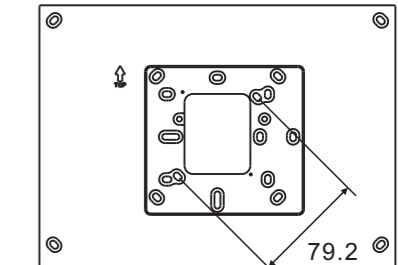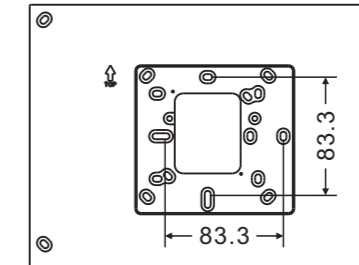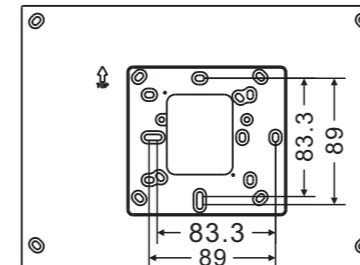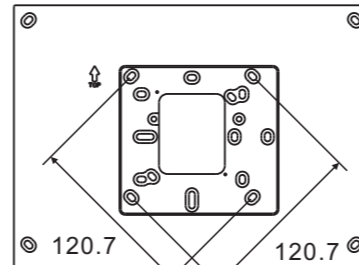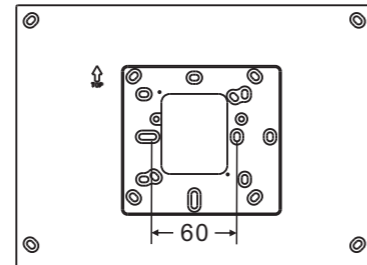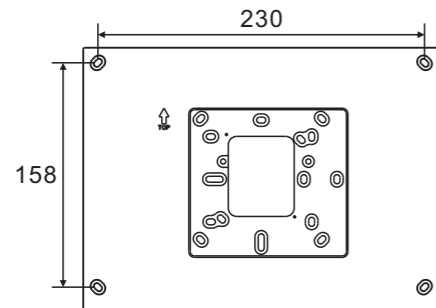


M2238.-.

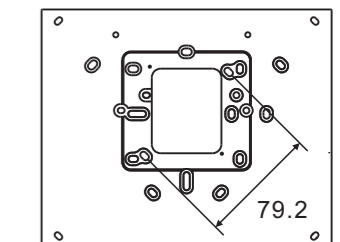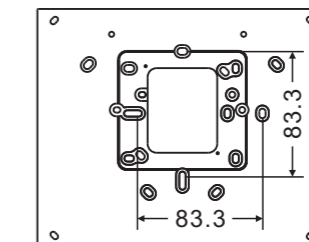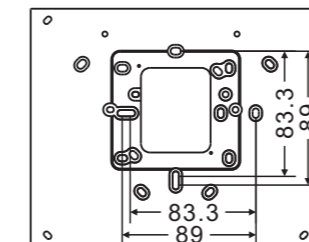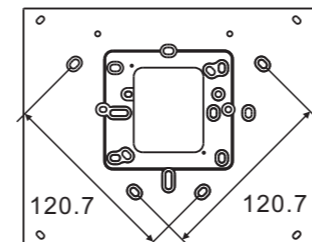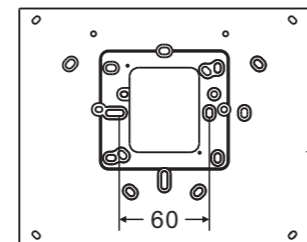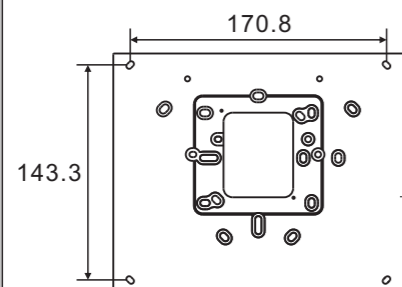



Surface-mounted installation

This installation method is not suitable for IPtouch (LAN+LAN)


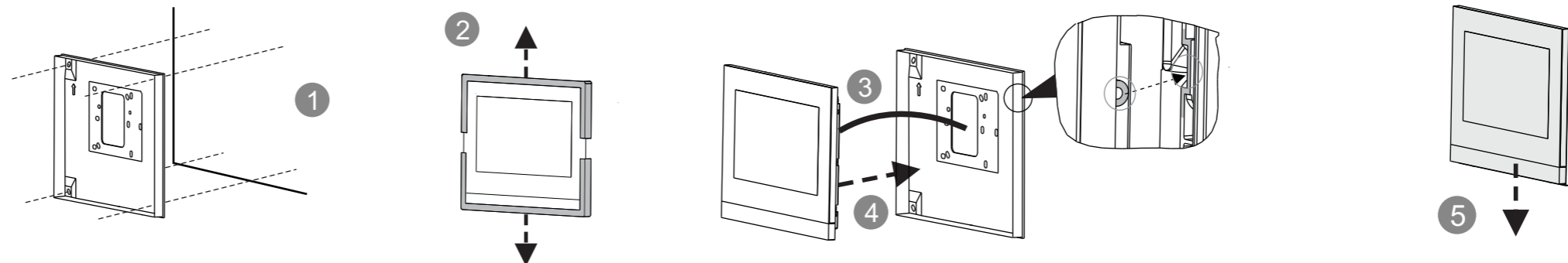


Desktop installation

 
This installation method is not suitable for IPtouch (LAN+LAN)

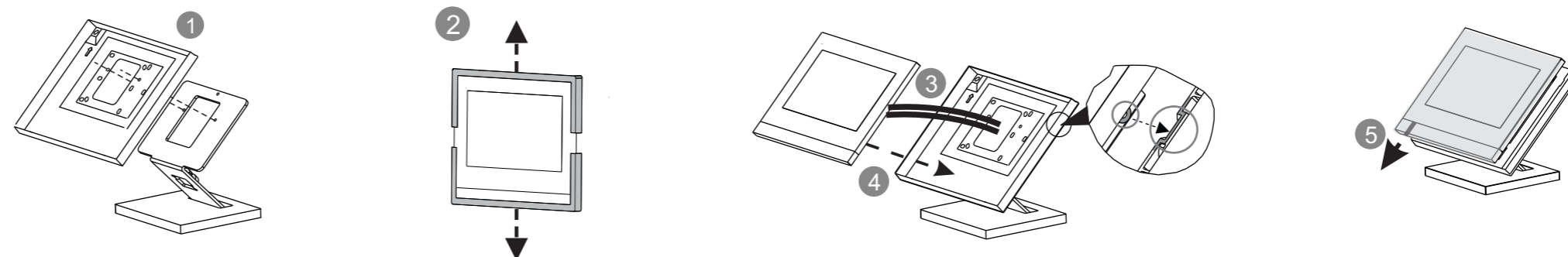

Flush-mounted installation

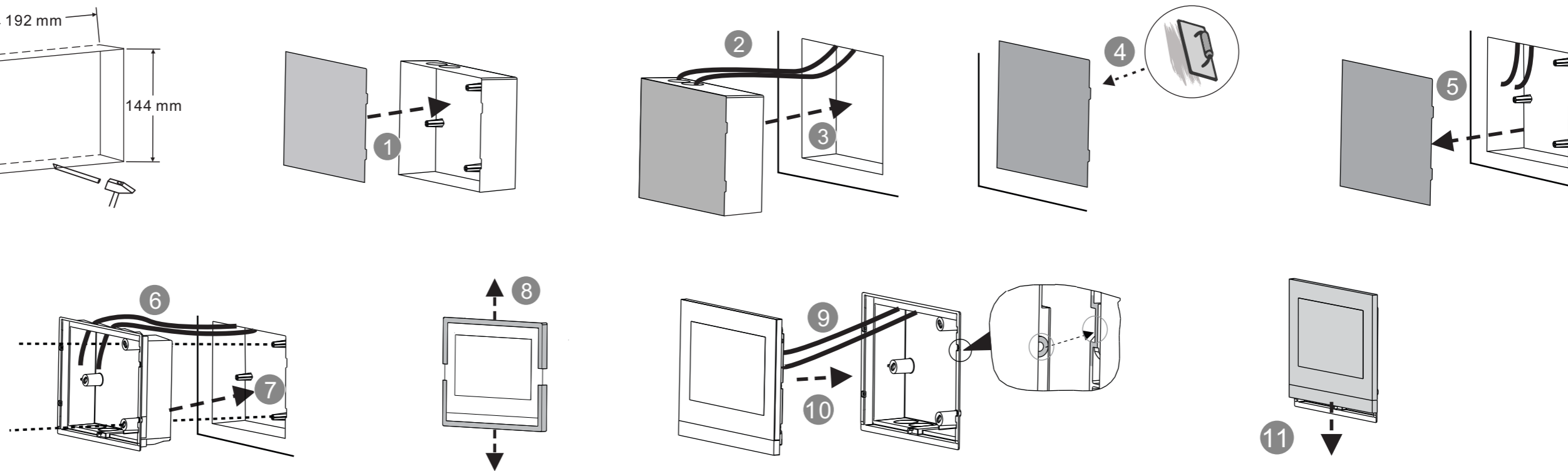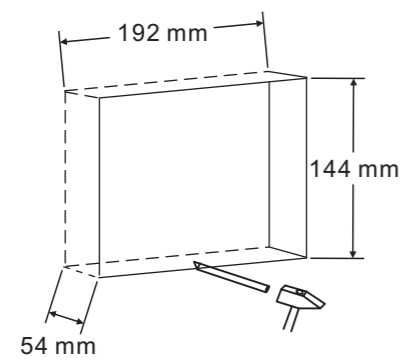


Cavity wall installation

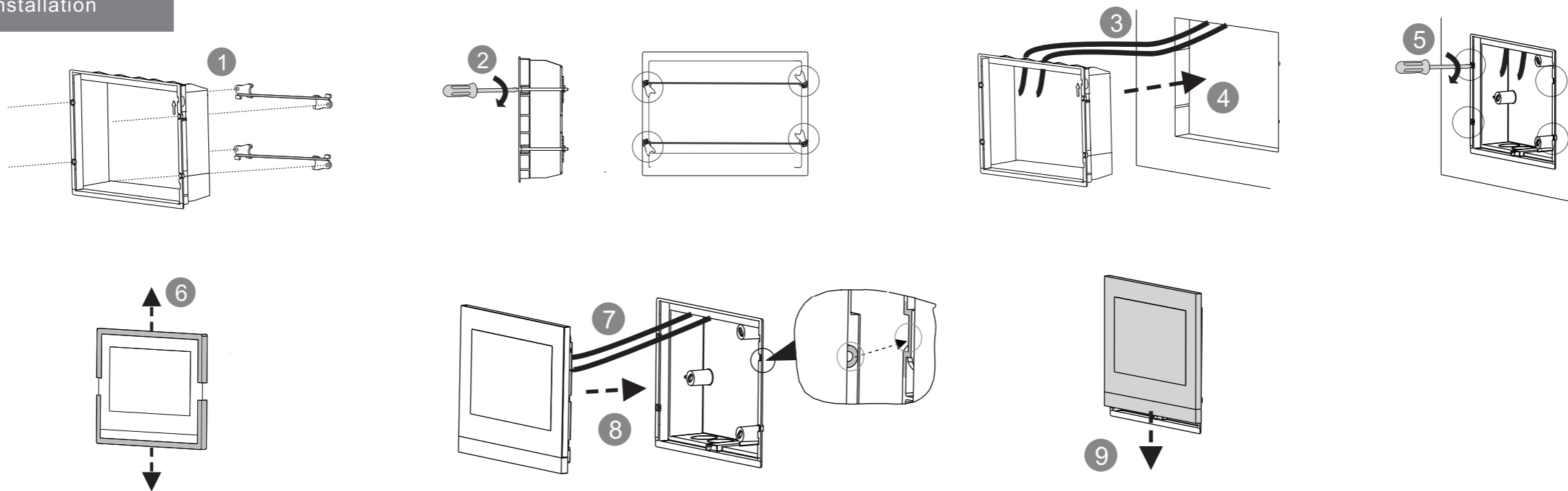

Replacing the end strip

(Not available for full glass panel)

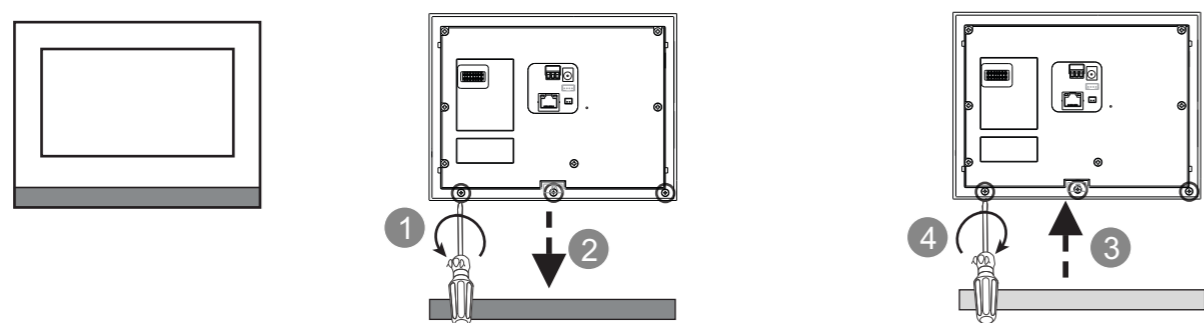

Dismantling

