
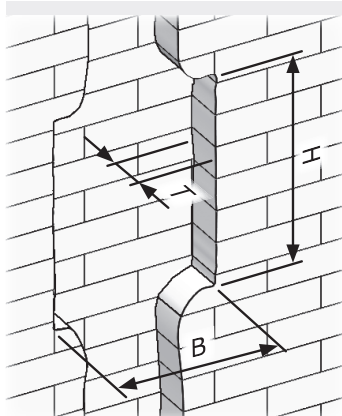


EN 60670-24 (PD)

www.striebelundjohn.com

- | | | |
|---------|---------|------------|
| UK624MB | UK620MV | UK636MV/MW |
| UK636MB | UK630MV | UK648MV/MW |
| UK648MB | UK640MV | UK660MV/MW |
| UK660MB | UK650MV | |

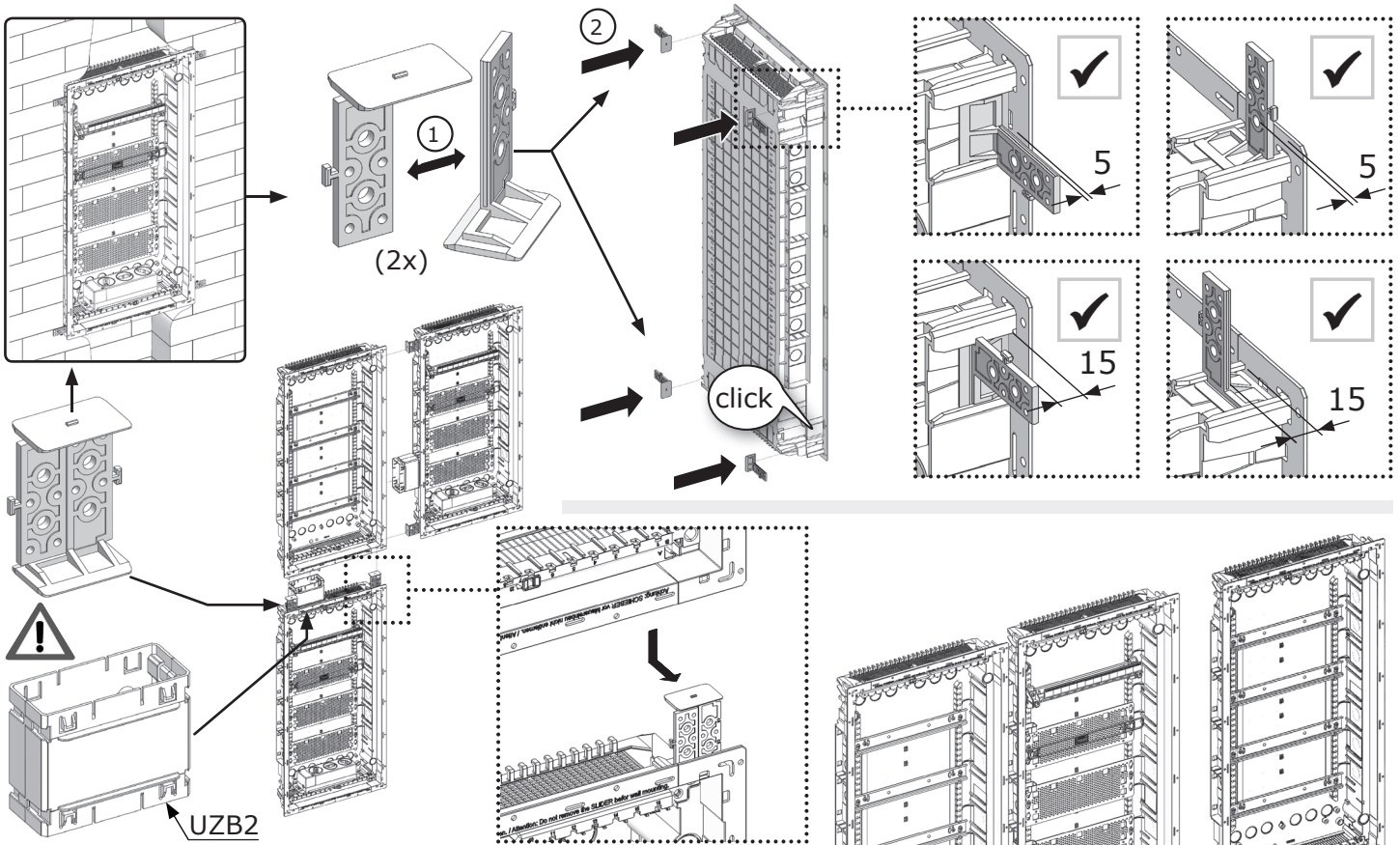

Matchcode	Nischenmaß		
	H	B	T
UK636MV/MW/MB	605	367	95
UK648MV/MW/MB	730	367	95
UK660MV/MW/MB	855	367	95
UK620MV/UK624MB	480	367	95
UK630MV/UK636MB	605	367	95
UK640MV/UK648MB	730	367	95
UK650MV/UK660MB	855	367	95

